




■ 12 VOLTS

■ 48 mm SQUARE HOUSING


MOTOR SPECIFICATIONS:

- Rated Voltage – 12V
- Rated Torque – 14.7 N • mm
- Rated Speed – 2560 rpm
- Rated Current – ≤ 520 mA
- No Load Speed – 3310 rpm
- No Load Current – ≤ 30 mA
- Weight – 240 g
- Rated Output – 3.84W
- Operating Temp. – -10°C to +60°C

For gearhead replacements, see A 2G31MB.... Series.

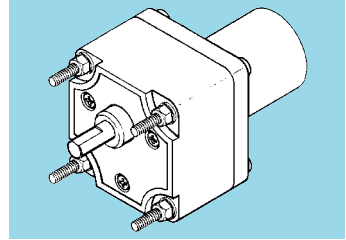

The projections shown are per ISO convention.

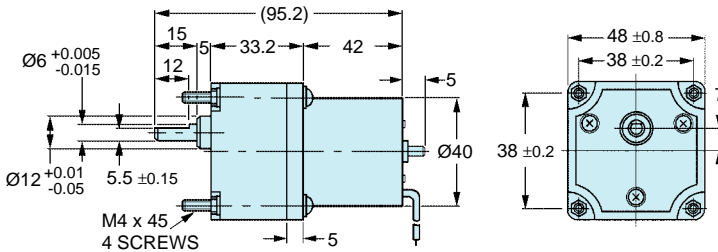


MATERIAL: Housing – Aluminum
 Shafts & Gears – Steel
 Bearings – Bronze

*Catalog Number	Ratio to 1	Rated Torque N • mm (oz. in.)	Speed rpm	
			Rated	No Load
D33S40MSTB0013D	12.67	147.1 (20.8)	204	261
D33S40MSTB0026D	26.31	294.2 (41.7)	98	126
D33S40MSTB0030D	29.56	294.2 (41.7)	87	112
D33S40MSTB0051D	50.67	490.3 (69.4)	52	65
D33S40MSTB0105D	105.23	981 (139)	25	31
D33S40MSTB0152D	152	981 (139)	18	22

*To be discontinued when present stock is depleted.

Similar performance gearhead with different motor is offered as D33S38M...Series. See index.

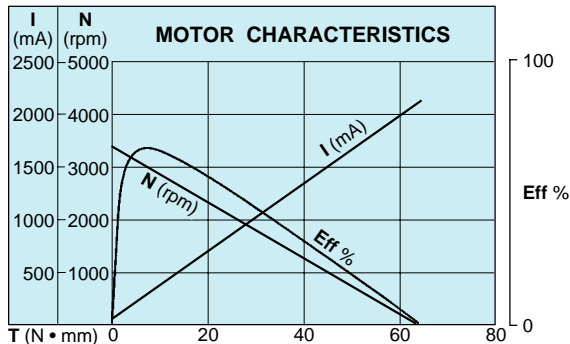



METRIC


Heavy-Duty D.C. Gearmotors - Size 48

- 24 VOLTS
- HIGH-SPEED
- 48 mm SQUARE HOUSING


MOTOR SPECIFICATIONS:

Rated Voltage – 24V
Rated Torque – 14.7 N-mm
Rated Speed – 3500 rpm
Rated Current – ≤ 419 mA
No Load Speed – 4200 rpm
No Load Current – ≤ 80 mA
Weight – 290 g
Rated Output – 5.4W
Operating Temp. – -10°C to +60°C

For gearhead replacements,
see A 2G31MB.... Series.

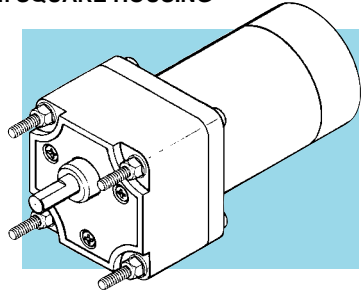

The projections shown are per ISO convention.

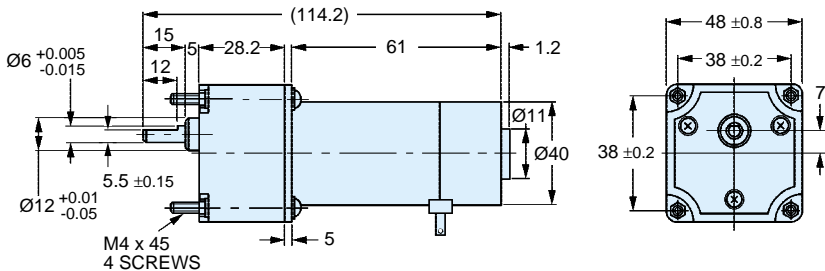

MATERIAL: Housing – Aluminum
Shafts & Gears – Steel
Bearings – Bronze

*Catalog Number	Ratio to 1	Rated Torque N-mm (oz. in.)	Speed rpm	
			Rated	No Load
D33S57M40B0013E	12.67	147.1 (20.8)	278	332
D33S57M40B0026E	26.31	294.2 (41.7)	132	160
D33S57M40B0030E	29.56	294.2 (41.7)	120	142
D33S57M40B0051E	50.67	490.3 (69.4)	70	83
D33S57M40B0105E	105.23	981 (139)	34	40
D33S57M40B0152E	152	981 (139)	25	28

*To be discontinued when present stock is depleted.

Similar performance gearhead with different motor is offered as D33S38M...Series. See index.

