



■ ISO CLASS 8

■ 20° PRESSURE ANGLE

■ 3 mm FACE WIDTH

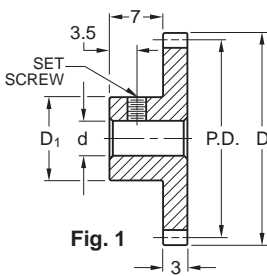


Fig. 1


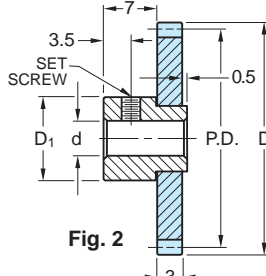


Fig. 2

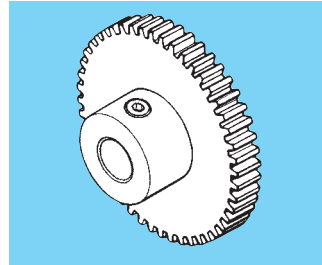

QUALITY CLASS

MATERIAL: Brass

Catalog Number	Fig. No.	No. of Teeth	P.D.	D	d* Bore H8	D ₁ Hub Dia.	Set Screw
A 1B 2MYKH7016	1	16	12	13.5	5	10	M3
A 1B 2MYKH7018		18	13.5	15		11	
A 1B 2MYKH7020		20	15	16.5	6	12	M4
A 1B 2MYKH7024		24	18	19.5			
A 1B 2MYKH7025		25	18.8	20.3			
A 1B 2MYKH7026		26	19.5	21			
A 1B 2MYKH7028		28	21	22.5	6	15	M4
A 1B 2MYKH7030		30	22.5	24			
A 1B 2MYKH7032		32	24	25.5			
A 1B 2MYKH7035		35	26.3	27.8			
A 1B 2MYKH7036		36	27	28.5	6	18	M4
A 1B 2MYKH7040		40	30	31.5			
A 1B 2MYKH7042		42	31.5	33			
A 1B 2MYKH7045		45	33.8	35.3			
A 1B 2MYKH7048		48	36	37.5	6	20	M4
A 1B 2MYKH7050		50	37.5	39			
A 1B 2MYKH7055	55	41.3	42.8				
A 1B 2MYKH7056	56	42	43.5				
A 1B 2MYKH7058	58	43.5	45	6	20	M4	
A 1B 2MYKH7060	60	45	46.5				
A 1B 2MYKH7062	62	46.5	48				
A 1B 2MYKH7064	64	48	49.5				
A 1B 2MYKH7065	65	48.8	50.3	6	20	M4	
A 1B 2MYKH7066	66	49.5	51				
A 1B 2MYKH7068	68	51	52.5				
A 1B 2MYKH7070	70	52.5	54				6
A 1B 2MYKH7072	72	54	55.5				
A 1B 2MYKH7075	75	56.3	57.8				
A 1B 2MYKH7080	80	60	61.5				
A 1B 2MYKH7084	84	63	64.5	6	20	M4	
A 1B 2MYKH7085	85	65.3	65.3				
A 1B 2MYKH7090	90	67.5	69				
A 1B 2MYKH7095	95	71.3	72.8				
A 1B 2MYKH7100	100	75	76.5	6	20	M4	
A 1B 2MYKH7105	105	78.8	80.3				
A 1B 2MYKH7110	110	82.5	84				
A 1B 2MYKH7115	115	86.3	87.8				
A 1B 2MYKH7120	120	90	91.5				

*Gears with 5 & 6 mm bore have a tolerance of + 0.018



See also "Pinions - Module 0.15 to 0.8".



■ ISO CLASS 8

■ 20° PRESSURE ANGLE

■ 3 mm FACE WIDTH

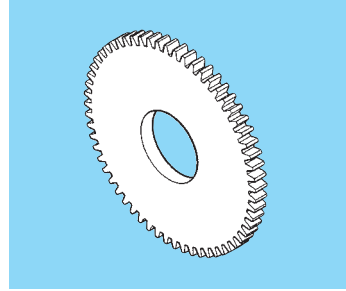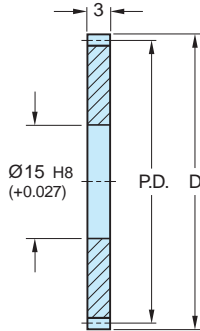

QUALITY CLASS

MATERIAL: Brass

Catalog Number	No. of Teeth	P.D.	D
A 1B 1MYKH7050	50	37.5	39
A 1B 1MYKH7055	55	41.3	42.8
A 1B 1MYKH7056	56	42	43.5
A 1B 1MYKH7058	58	43.5	45
A 1B 1MYKH7060	60	45	46.5
A 1B 1MYKH7062	62	46.5	48
A 1B 1MYKH7064	64	48	49.5
A 1B 1MYKH7065	65	48.8	50.3
A 1B 1MYKH7066	66	49.5	51
A 1B 1MYKH7068	68	51	52.5
A 1B 1MYKH7070	70	52.5	54
A 1B 1MYKH7072	72	54	55.5
A 1B 1MYKH7075	75	56.3	57.8
A 1B 1MYKH7080	80	60	61.5
A 1B 1MYKH7084	84	63	64.5
A 1B 1MYKH7085	85	65.3	65.3
A 1B 1MYKH7090	90	67.5	69
A 1B 1MYKH7095	95	71.3	72.8
A 1B 1MYKH7100	100	75	76.5
A 1B 1MYKH7105	105	78.8	80.3
A 1B 1MYKH7110	110	82.5	84
A 1B 1MYKH7115	115	86.3	87.8
A 1B 1MYKH7120	120	90	91.5

Did You Know?

...You can obtain additional literature by viewing our "home page" on the INTERNET?

<http://www.sdp-si.com>