 



THREADED PLUG
BALL END PLUG

PHONE: 516.328.3300 • FAX: 516.326.8827 • WWW.SDP-SI.COM

MATERIAL:

Cables - Stainless Steel, Nylon Coated
Fittings - Brass

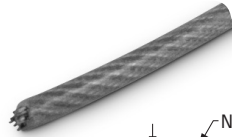

INCH COMPONENT

Catalog Number	Cable O.D.	A Δ Wire Dia.	Breaking Strength lbf
Sold in Multiples of 10 Feet			
A 6X 9-024	.024	.018	40
A 6X 9-034	.034	.027	90
A 6X 9-037	.037	.031	120
A 6X 9-044	.044	.036	160
A 6X 9-062	1/16	3/64	270
A 6X 9-094	3/32	1/16	480
A 6X 9-125	1/8	3/32	920

Nylon coating protects wire and pulleys from abrasion and seals in lubrication.

Δ In selecting cable fittings, use "A" diameter as it is recommended that nylon covering be stripped prior to swaging.

 


Fig. 1

 


Fig. 2



INCH COMPONENT

Catalog Number	A Wire Dia.	T Thread	F* Flats	L*	Diameter Before Swaging
Fig. 1 Threaded Plug - Priced Per 10 Pieces					
A 6B 9-01005	.010 - .027	#5-40	7/64	1	1/8
A 6B 9-02805	.028 - .037	#5-40	7/64	1	1/8
A 6B 9-03805	.038 - .048	#5-40	7/64	1	1/8
A 6B 9-02808	.028 - .037	#8-32	9/64	1	5/32
A 6B 9-03808	.038 - .048	#8-32	9/64	1	5/32
A 6B 9-04710	3/64	#10-24	5/32	1-1/8	3/16
A 6B 9-06310	1/16	#10-24	5/32	1-1/8	3/16
Fig. 2 Ball End Plug - Priced Per 10 Pieces					
A 6B 9-010125	.010 - .027	—	.105	1/8	1/8
A 6B 9-028125	.028 - .037	—	.105	1/8	1/8
A 6B 9-038125	.038 - .046	—	.105	1/8	1/8
A 6B 9-010250	.010 - .027	—	.105	1/4	1/8
A 6B 9-028250	.028 - .037	—	.105	1/4	1/8
A 6B 9-038250	.038 - .046	—	.105	1/4	1/8
A 6B 9-010395	.010 - .027	—	1/8	25/64	5/32
A 6B 9-028395	.028 - .037	—	1/8	25/64	5/32
A 6B 9-038395	.038 - .048	—	1/8	25/64	5/32
A 6B 9-049395	.049 - .065	—	1/8	25/64	5/32
A 6B 9-047540	3/64	—	5/32	17/32	3/16
A 6B 9-063540	1/16	—	5/32	17/32	3/16

Ball End is rated at 50% of rated breaking strength of cable.

* These dimensions obtained when fittings are swaged to "F" dimensions. Before swage, the fitting is round.