

URETHANE SURFACE
WITHOUT BEARING

PHONE: 516.328.3300 • FAX: 516.326.8827 • WWW.SDP-SI.COM

> MATERIAL:

- Roller** - Urethane 60 Durometer
Ground Outside Diameter
- Sleeve** - Aluminum

All feed rollers supplied with 2 set screws.


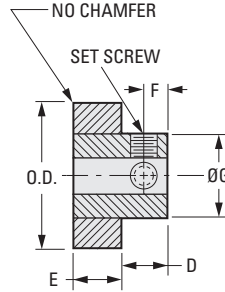


Fig.1

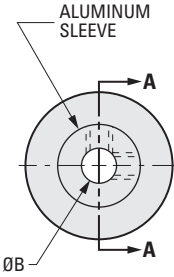

SECTION A-A


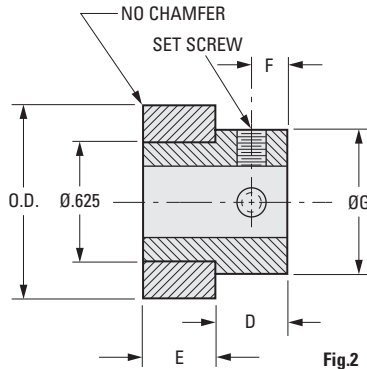


Fig.2

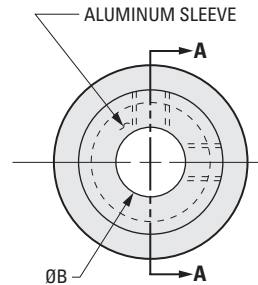

SECTION A-A

INCH COMPONENT

Catalog Number	Fig. No.	O.D. ± .003	B Bore +.0005 -0.0000	E Face Width ± .010	D Hub Proj.	F	G Sleeve O.D.	Set Screw
A 7T 5-UR05618	1	.562	.1875	.250	.250	.125	.437	#4-40
A 7T 5-UR07518	1	.750	.1875	.250	.250	.125	.437	#4-40
A 7T 5-UR06225	1	.625	.2500	.375	.250	.125	.500	#6-32
A 7T 5-UR07525	1	.750	.2500	.375	.250	.125	.500	#6-32
A 7T 5-UR08725	1	.875	.2500	.375	.250	.125	.500	#6-32
A 7T 5-UR10037	2	1.000	.3750	.375	.375	.187	.750	#10-32
A 7T 5-UR12537	1	1.250	.3750	.375	.375	.187	.812	#10-32
A 7T 5-UR15037	1	1.500	.3750	.375	.375	.187	1.000	#10-32
A 7T 5-UR15050	1	1.500	.5000	.500	.500	.250	1.000	1/4-20
A 7T 5-UR17550	1	1.750	.5000	.500	.500	.250	1.250	1/4-20
A 7T 5-UR20050	1	2.000	.5000	.500	.500	.250	1.375	1/4-20



WITHOUT BEARING
URETHANE SURFACE

PHONE: 516.328.3300 • FAX: 516.326.8827 • WWW.SDP-SI.COM

► MATERIAL:

- Roller - Urethane 60 Durometer
- Ground Outside Diameter
- Sleeve - Aluminum



Fig. 1

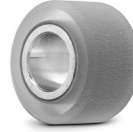


Fig. 2

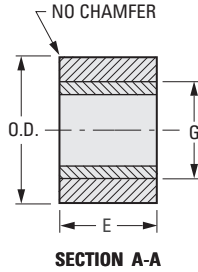


Fig. 1 Without Chamfer



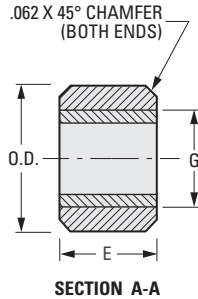


Fig. 2 With Chamfer

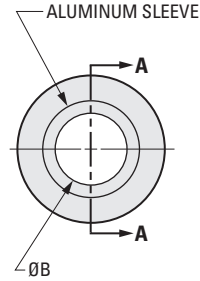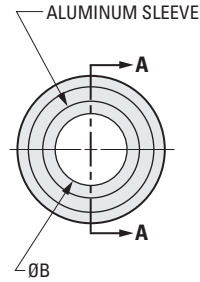

INCH COMPONENT

Catalog Number	Fig. No.	O.D. ± .003	B Bore	B Tolerance	E Face Width ± .010	G Sleeve O.D.
A 7M 5-UR05025A	1	.500	.2500	+.001/- .000	.250	.344
A 7M 5-UR05025B	1	.500	.2500	+.0005/- .0000	.718	.344
A 7M 5-UR05025C	1	.500	.2500	+.001/- .000	.500	.344
A 7M 5-UR06737	1	.672	.3750	+.0005/- .0000	.250	.500
A 7M 5-UR07537	1	.750	.3750	+.0005/- .0000	.500	.500
A 7M 5-UR07543	1	.750	.4375	+.0005/- .0000	.500	.500
A 7M 5-UR08137	2	.813	.3750	+.0005/- .0000	.500	.500
A 7M 5-UR09237	1	.922	.3750	+.0005/- .0000	.484	.688
A 7M 5-UR11237A	1	1.125	.3750	+.0005/- .0000	.438	.500
A 7M 5-UR11237B	1	1.125	.3750	+.0005/- .0000	.688	.500
A 7M 5-UR19837	1	1.988	.3750	+.001/- .000	.688	1.375
A 7M 5-UR19850A	1	1.988	.5000	+.001/- .000	.750	1.375
A 7M 5-UR19850B	1	1.988	.5000	+.001/- .000	1.000	1.375