

FOR .110 & .168 FACE SPROCKETS


PHONE: 516.328.3300 • FAX: 516.326.8827 • WWW.SDP-SI.COM

> **MATERIAL:**

Ladder Chain - Steel, Brass, High-Tensile Steel or Stainless Steel

> **SPECIFICATION:**

These sprockets can be used with ladder or roller chains.

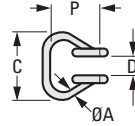

INCH COMPONENT

Catalog Number	Material	P Pitch	Links Per Foot	A Wire Dia.	C Outside Width	D Inside Width	Yield Point lbf
Ladder Chain - Priced Per Foot							
A 6C 8-25	Steel	1/4	48	.054	.335	.130	30
A 6C88-25	High-Tensile Steel	1/4	48	.054	.335	.130	90
A 6B 8-25	Brass	1/4	48	.054	.335	.130	26
A 6Y 8-25	Stainless Steel	1/4	48	.054	.335	.130	30
A 6B 8-37	Brass	3/8	32	.080	.555	.205	45
A 6Y 8-37	Stainless Steel	3/8	32	.080	.555	.205	80

Catalog Number (Ref.)	Pitch	Sprocket Material	Catalog Page
Sprockets Locator			
A 6T 7-25...	1/4	Nylon	2-229
A 6M 7-25...	1/4	Acetal	2-230
A 6X 7-25...	1/4	Stainless Steel	2-225
A 6C 7-25B..	1/4	Steel	2-226
A 6C 7-25...	1/4	Steel	2-227
A 6M 7-37..	3/8	Nylatron	2-232



A 6T 7-2528



A 6M 7-25ACE



A 6C 7-25B09



A 6M 7-3709