

DIN 85


PHONE: 516.328.3300 • FAX: 516.326.8827 • WWW.SDP-SI.COM

➤ **MATERIAL:**

304 Stainless Steel

➤ **SPECIFICATION:**

Priced Per 100 Pieces

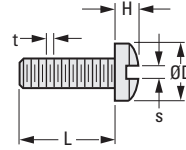

**METRIC COMPONENT**

| Catalog Number   | Thread Size | L Length |
|------------------|-------------|----------|
| MD0085MXO020X006 | M2          | 6        |
| MD0085MXO020X010 | M2          | 10       |
| MD0085MXO025X006 | M2.5        | 6        |
| MD0085MXO025X008 | M2.5        | 8        |
| MD0085MXO025X010 | M2.5        | 10       |
| MD0085MXO025X012 | M2.5        | 12       |
| MD0085MXO025X016 | M2.5        | 16       |
| MD0085MXO025X020 | M2.5        | 20       |
| MD0085MXO025X025 | M2.5        | 25       |
| MD0085MXO030X006 | M3          | 6        |
| MD0085MXO030X008 | M3          | 8        |
| MD0085MXO030X016 | M3          | 16       |
| MD0085MXO030X020 | M3          | 20       |
| MD0085MXO030X030 | M4          | 30       |
| MD0085MXO040X006 | M4          | 6        |

| Catalog Number   | Thread Size | L Length |
|------------------|-------------|----------|
| MD0085MXO040X010 | M4          | 10       |
| MD0085MXO040X012 | M4          | 12       |
| MD0085MXO040X016 | M4          | 16       |
| MD0085MXO040X020 | M4          | 20       |
| MD0085MXO040X025 | M4          | 25       |
| MD0085MXO040X030 | M4          | 30       |
| MD0085MXO050X008 | M5          | 8        |
| MD0085MXO050X010 | M5          | 10       |
| MD0085MXO050X012 | M5          | 12       |
| MD0085MXO050X016 | M5          | 16       |
| MD0085MXO050X020 | M5          | 20       |
| MD0085MXO050X025 | M5          | 25       |
| MD0085MXO050X030 | M5          | 30       |
| MD0085MXO060X012 | M6          | 12       |
| MD0085MXO060X030 | M6          | 30       |

| Dimensions | Thread Size |      |     |     |     |     |
|------------|-------------|------|-----|-----|-----|-----|
|            | M2          | M2.5 | M3  | M4  | M5  | M6  |
| t          | 0.4         | 0.45 | 0.5 | 0.7 | 0.8 | 1   |
| D          | 3.7         | 5    | 6   | 8   | 10  | 12  |
| H          | 1.2         | 1.5  | 1.8 | 2.4 | 3   | 3.6 |
| s          | 0.5         | 0.6  | 0.8 | 1   | 1.2 | 1.6 |

DIN 84


PHONE: 516.328.3300 • FAX: 516.326.8827 • WWW.SDP-SI.COM

**> MATERIAL:**

304 Stainless Steel

**> SPECIFICATION:**

Priced Per 100 Pieces

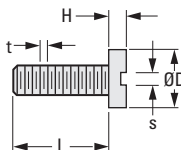

### METRIC COMPONENT

| Catalog Number   | Thread Size | L Length |
|------------------|-------------|----------|
| MD0084MXO016X004 | M1.6        | 4        |
| MD0084MXO016X006 | M1.6        | 6        |
| MD0084MXO020X003 | M2          | 3        |
| MD0084MXO020X004 | M2          | 4        |
| MD0084MXO020X005 | M2          | 5        |
| MD0084MXO020X006 | M2          | 6        |
| MD0084MXO020X008 | M2          | 8        |
| MD0084MXO020X010 | M2          | 10       |
| MD0084MXO020X016 | M2          | 16       |
| MD0084MXO020X020 | M2          | 20       |
| MD0084MXO025X005 | M2.5        | 5        |
| MD0084MXO025X006 | M2.5        | 6        |
| MD0084MXO025X008 | M2.5        | 8        |
| MD0084MXO025X010 | M2.5        | 10       |
| MD0084MXO025X012 | M2.5        | 12       |
| MD0084MXO025X016 | M2.5        | 16       |
| MD0084MXO025X020 | M2.5        | 20       |
| MD0084MXO030X005 | M3          | 5        |
| MD0084MXO030X006 | M3          | 6        |
| MD0084MXO030X008 | M3          | 8        |
| MD0084MXO030X010 | M3          | 10       |
| MD0084MXO030X012 | M3          | 12       |
| MD0084MXO030X020 | M3          | 20       |
| MD0084MXO030X025 | M3          | 25       |
| MD0084MXO035X008 | M3.5        | 8        |
| MD0084MXO035X012 | M3.5        | 12       |

| Catalog Number   | Thread Size | L Length |
|------------------|-------------|----------|
| MD0084MXO035X016 | M3.5        | 16       |
| MD0084MXO040X006 | M4          | 6        |
| MD0084MXO040X008 | M4          | 8        |
| MD0084MXO040X010 | M4          | 10       |
| MD0084MXO040X012 | M4          | 12       |
| MD0084MXO040X016 | M4          | 16       |
| MD0084MXO040X020 | M4          | 20       |
| MD0084MXO040X025 | M4          | 25       |
| MD0084MXO040X030 | M4          | 30       |
| MD0084MXO040X035 | M4          | 35       |
| MD0084MXO040X040 | M4          | 40       |
| MD0084MXO050X010 | M5          | 10       |
| MD0084MXO050X012 | M5          | 12       |
| MD0084MXO050X016 | M5          | 16       |
| MD0084MXO050X020 | M5          | 20       |
| MD0084MXO050X025 | M5          | 25       |
| MD0084MXO050X030 | M5          | 30       |
| MD0084MXO050X035 | M5          | 35       |
| MD0084MXO050X040 | M5          | 40       |
| MD0084MXO060X008 | M6          | 8        |
| MD0084MXO060X010 | M6          | 10       |
| MD0084MXO060X012 | M6          | 12       |
| MD0084MXO060X016 | M6          | 16       |
| MD0084MXO060X020 | M6          | 20       |
| MD0084MXO060X025 | M6          | 25       |
| MD0084MXO060X030 | M6          | 30       |

| Dimensions | Thread Size |     |      |     |      |     |     |     |
|------------|-------------|-----|------|-----|------|-----|-----|-----|
|            | M1.6        | M2  | M2.5 | M3  | M3.5 | M4  | M5  | M6  |
| t          | 0.35        | 0.4 | 0.45 | 0.5 | 0.6  | 0.7 | 0.8 | 1   |
| D          | 3           | 3.8 | 4.5  | 5.5 | 6    | 7   | 8.5 | 10  |
| H          | 1           | 1.3 | 1.6  | 2   | 2.5  | 2.6 | 3.3 | 3.6 |
| s          | 0.4         | 0.5 | 0.6  | 0.8 | 0.9  | 1   | 1.2 | 1.6 |

# FLAT HEAD MACHINE SCREWS


**SDP/SI**

DIN 963  
90° FLAT HEAD

PHONE: 516.328.3300 • FAX: 516.326.8827 • WWW.SDP-SI.COM

**> MATERIAL:**  
304 Stainless Steel

**> SPECIFICATION:**  
Priced Per 100 Pieces

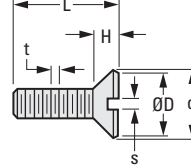

## METRIC COMPONENT

| Catalog Number   | Thread Size | L Length |
|------------------|-------------|----------|
| MD0963MXO020X004 | M2          | 4        |
| MD0963MXO020X005 | M2          | 5        |
| MD0963MXO020X006 | M2          | 6        |
| MD0963MXO020X008 | M2          | 8        |
| MD0963MXO020X010 | M2          | 10       |
| MD0963MXO020X012 | M2          | 12       |
| MD0963MXO025X004 | M2.5        | 4        |
| MD0963MXO025X006 | M2.5        | 6        |
| MD0963MXO025X008 | M2.5        | 8        |
| MD0963MXO025X010 | M2.5        | 10       |
| MD0963MXO025X012 | M2.5        | 12       |
| MD0963MXO025X016 | M2.5        | 16       |
| MD0963MXO025X020 | M2.5        | 20       |
| MD0963MXO030X005 | M3          | 5        |
| MD0963MXO030X006 | M3          | 6        |
| MD0963MXO030X008 | M3          | 8        |

| Catalog Number   | Thread Size | L Length |
|------------------|-------------|----------|
| MD0963MXO030X010 | M3          | 10       |
| MD0963MXO030X012 | M3          | 12       |
| MD0963MXO030X016 | M3          | 16       |
| MD0963MXO030X020 | M3          | 20       |
| MD0963MXO030X025 | M3          | 25       |
| MD0963MXO040X006 | M4          | 6        |
| MD0963MXO040X008 | M4          | 8        |
| MD0963MXO040X010 | M4          | 10       |
| MD0963MXO040X012 | M4          | 12       |
| MD0963MXO040X016 | M4          | 16       |
| MD0963MXO050X008 | M5          | 8        |
| MD0963MXO050X010 | M5          | 10       |
| MD0963MXO050X012 | M5          | 12       |
| MD0963MXO050X016 | M5          | 16       |
| MD0963MXO050X020 | M5          | 20       |

| Dimensions | Thread Size |      |      |     |      |
|------------|-------------|------|------|-----|------|
|            | M2          | M2.5 | M3   | M4  | M5   |
| t          | 0.4         | 0.45 | 0.5  | 0.7 | 0.8  |
| D          | 3.8         | 4.7  | 5.6  | 7.5 | 9.2  |
| d (c'sink) | 4.6         | 5.7  | 6.5  | 8.6 | 10.4 |
| H          | 1.2         | 1.5  | 1.65 | 2.2 | 2.5  |
| s          | 0.5         | 0.6  | 0.8  | 1   | 1.2  |