

HEXAGONAL NUTS



PHONE: 516.328.3300 • FAX: 516.326.8827 • WWW.SDP-SI.COM

- ▶ **MATERIAL:**
Alloy Steel or 18-8 Stainless Steel
- ▶ **FINISH:**
Alloy Steel, Zinc Plated
- ▶ **SPECIFICATION:**
Priced Per 100 Pieces


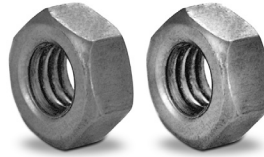


Fig. 1

Fig. 2

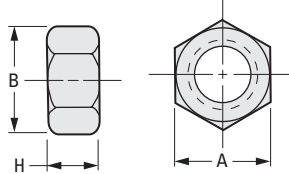

INCH COMPONENT


Catalog Number	Thread Size	A +.00 -.01	B +.000 -.015	H +.000 -.015
Fig. 1 Alloy Steel, Zinc Plated				
A 9Q18-080	#0-80	.156	.180	.050
A 9Q18-256	#2-56	.188	.217	.066
A 9Q18-440	#4-40	.250	.289	.098
A 9Q18-632	#6-32	.312	.361	.114
A 9Q18-832	#8-32	.344	.397	.130
A 9Q18-024	#10-24	.375	.433	.130
A 9Q18-032	#10-32	.375	.433	.130
A 9Q18-120	1/4-20	.438	.505	.193
A 9Q18-518	5/16-18	.500	.577	.258
Fig. 2 18-8 Stainless Steel				
A 9X18-080	#0-80	.156	.180	.050
A 9X18-256	#2-56	.188	.217	.066
A 9X18-440	#4-40	.250	.289	.098
A 9X18-632	#6-32	.312	.361	.114
A 9X18-832	#8-32	.344	.397	.130
A 9X18-032	#10-32	.375	.433	.130
A 9X18-120	1/4-20	.438	.505	.193

HEXAGONAL NYLON INSERT LOCKNUTS

SDP/SI

VIBRATION-RESISTANT
NO MARRING OF THREADS
REUSABLE
INSERT EFFECTIVE UP TO 250°F

PHONE: 516.328.3300 • FAX: 516.326.8827 • WWW.SDP-SI.COM

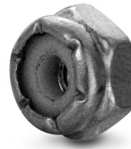


> MATERIAL:

Locknut - 303 Stainless Steel
Insert - Nylon

> SPECIFICATION:

Priced Per 100 Pieces

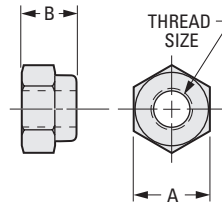

INCH COMPONENT

Catalog Number	Thread Size	A	B
A 9X23-0256	#2-56	.250	.140
A 9X23-0440	#4-40	.250	.140
A 9X23-0632	#6-32	.313	.172
A 9X23-0832	#8-32	.344	.234
A 9X23-1032	#10-32	.375	.234
A 9X23-2520	1/4-20	.438	.313

1

2

3

4

5

6

7

8

9

10

11

12

13

14

15

16

17

18

19

20

I

PLASTIC HEXAGONAL NUTS

SDPSI

LIGHTWEIGHT
NONCORROSIVE
VIBRATION-RESISTANT
NONCONDUCTIVE
ANTIMAGNETIC

PHONE: 516.328.3300 • FAX: 516.326.8827 • WWW.SDP-SI.COM



R

T


1

➤ **MATERIAL:**

Nylon (6/6 Natural)

➤ **SPECIFICATION:**

Priced Per 100 Pieces

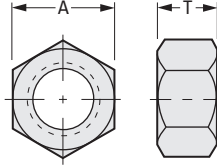

2

3

INCH COMPONENT

Catalog Number	Thread Size	A	T
A 9M62-0256	#2-56	3/16	1/16
A 9M62-0440	#4-40	1/4	3/32
A 9M62-0632	#6-32	5/16	1/8
A 9M62-0832	#8-32	11/32	1/8
A 9M62-1024	#10-24	3/8	9/64
A 9M62-1032	#10-32	3/8	9/64
A 9M62-2520	1/4-20	7/16	13/64
A 9M62-3118	5/16-18	1/2	17/64
A 9M62-3716	3/8-16	9/16	21/64
A 9M62-5013	1/2-13	3/4	7/16
A 9M62-6211	5/8-11	15/16	35/64

4

5

6

7

8

9

10

11

12

13

14

15

16

NYLON HEX LOCK NUTS


PHONE: 516.328.3300 • FAX: 516.326.8827 • WWW.SDP-SI.COM

SELF-THREADING
LOCKING
INSULATING



> MATERIAL:
Nylon (Zytel 101)

> SPECIFICATION:
Priced Per 100 Pieces

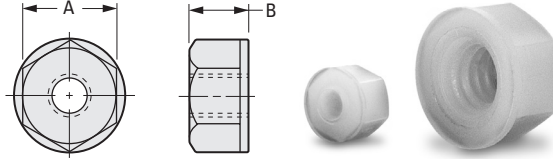

INCH COMPONENT


Catalog Number	Thread Size	A ± .010	B ± .010
Self-Threading			
A 9M64-0256	#2-56	.180	.140
A 9M64-0440	#4-40	.250	.200
A 9M64-0632	#6-32	.305	.230
A 9M64-0832	#8-32	.335	.250
A 9M64-1024	#10-24	.365	.275
A 9M64-1032	#10-32	.425	.275
A 9M64-2520	1/4-20	.425	.275
Threaded			
A 9M64-2520T	1/4-20	.425	.275

NYLON HEX CAP NUTS

LIGHTWEIGHT
NONCORROSIVE
NONCONDUCTIVE
VIBRATION-RESISTANT

> MATERIAL:
Nylon (Zytel 101)

> SPECIFICATION:
Priced Per 100 Pieces

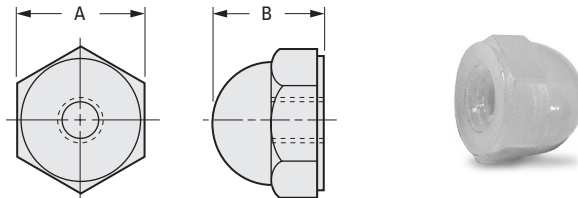

INCH COMPONENT

Catalog Number	Thread Size	A ± .010	B Ref.
A 9M65-0440	#4-40	.250	.280
A 9M65-0632	#6-32	.305	.345
A 9M65-0832	#8-32	.330	.375
A 9M65-1024	#10-24	.365	.400
A 9M65-1032	#10-32	.425	.475
A 9M65-2520	1/4-20	.425	.475