

CUP POINT

 
PHONE: 516.328.3300 • FAX: 516.326.8827 • WWW.SDP-SI.COM

> **MATERIAL:**

Stainless Steel

> **SPECIFICATION:**

Priced Per 100 Pieces



- I
- R
- T
- 1
- 2
- 3
- 4
- 5
- 6
- 7
- 8
- 9
- 10**
- 11
- 12
- 13
- 14
- 15
- 16

INCH COMPONENT

Catalog Number	Thread Size	L Length
A 9X17-008002	#0-80	1/16
A 9X17-008003	#0-80	3/32
A 9X17-008004	#0-80	1/8
A 9X17-008006	#0-80	3/16
A 9X17-008008	#0-80	1/4
A 9X17-025602	#2-56	1/16
A 9X17-025603	#2-56	3/32
A 9X17-025604	#2-56	1/8
A 9X17-025606	#2-56	3/16
A 9X17-025608	#2-56	1/4
A 9X17-044004	#4-40	1/8
A 9X17-044006	#4-40	3/16
A 9X17-044008	#4-40	1/4
A 9X17-063204	#6-32	1/8
A 9X17-063206	#6-32	3/16
A 9X17-063208	#6-32	1/4
A 9X17-063210	#6-32	5/16
A 9X17-063212	#6-32	3/8
A 9X17-064004	#6-40	1/8
A 9X17-064006	#6-40	3/16
A 9X17-064008	#6-40	1/4
A 9X17-064010	#6-40	5/16
A 9X17-083204	#8-32	1/8
A 9X17-083206	#8-32	3/16

Catalog Number	Thread Size	L Length
A 9X17-083208	#8-32	1/4
A 9X17-083210	#8-32	5/16
A 9X17-083212	#8-32	3/8
A 9X17-083216	#8-32	1/2
A 9X17-102404	#10-24	1/8
A 9X17-102406	#10-24	3/16
A 9X17-102408	#10-24	1/4
A 9X17-102414	#10-24	7/16
A 9X17-102416	#10-24	1/2
A 9X17-103204	#10-32	1/8
A 9X17-103206	#10-32	3/16
A 9X17-103208	#10-32	1/4
A 9X17-103210	#10-32	5/16
A 9X17-103212	#10-32	3/8
A 9X17-103216	#10-32	1/2
A 9X17-103220	#10-32	5/8
A 9X17-103224	#10-32	3/4
A 9X17-252006	1/4-20	3/16
A 9X17-252008	1/4-20	1/4
A 9X17-252010	1/4-20	5/16
A 9X17-252012	1/4-20	3/8
A 9X17-252016	1/4-20	1/2
A 9X17-252020	1/4-20	5/8
A 9X17-252024	1/4-20	3/4
A 9X17-311824	5/16-18	3/4
A 9X17-311828	5/16-18	7/8

CUP POINT

 
PHONE: 516.328.3300 • FAX: 516.326.8827 • WWW.SDP-SI.COM

> MATERIAL:

Steel, Black Oxide

> SPECIFICATION:

Priced Per 100 Pieces



- I
- R
- T
- 1
- 2
- 3
- 4
- 5
- 6
- 7
- 8
- 9
- 10**
- 11
- 12
- 13
- 14
- 15
- 16

INCH COMPONENT

Catalog Number	Thread Size	L Length
A 9Q17-008002	#0-80	1/16
A 9Q17-008003	#0-80	3/32
A 9Q17-008004	#0-80	1/8
A 9Q17-008006	#0-80	3/16
A 9Q17-008008	#0-80	1/4
A 9Q17-025602	#2-56	1/16
A 9Q17-025603	#2-56	3/32
A 9Q17-025604	#2-56	1/8
A 9Q17-025606	#2-56	3/16
A 9Q17-025608	#2-56	1/4
A 9Q17-044003	#4-40	3/32
A 9Q17-044004	#4-40	1/8
A 9Q17-044006	#4-40	3/16
A 9Q17-044008	#4-40	1/4
A 9Q17-044010	#4-40	5/16
A 9Q17-063204	#6-32	1/8
A 9Q17-063206	#6-32	3/16
A 9Q17-063208	#6-32	1/4
A 9Q17-063210	#6-32	5/16
A 9Q17-063212	#6-32	3/8
A 9Q17-064004	#6-40	1/8
A 9Q17-064006	#6-40	3/16
A 9Q17-064008	#6-40	1/4
A 9Q17-064010	#6-40	5/16
A 9Q17-083204	#8-32	1/8
A 9Q17-083206	#8-32	3/16
A 9Q17-083208	#8-32	1/4
A 9Q17-083210	#8-32	5/16
A 9Q17-083212	#8-32	3/8

Catalog Number	Thread Size	L Length
A 9Q17-083216	#8-32	1/2
A 9Q17-102404	#10-24	1/8
A 9Q17-102406	#10-24	3/16
A 9Q17-102408	#10-24	1/4
A 9Q17-102410	#10-24	5/16
A 9Q17-102412	#10-24	3/8
A 9Q17-102414	#10-24	7/16
A 9Q17-102416	#10-24	1/2
A 9Q17-103204	#10-32	1/8
A 9Q17-103206	#10-32	3/16
A 9Q17-103208	#10-32	1/4
A 9Q17-103210	#10-32	5/16
A 9Q17-103212	#10-32	3/8
A 9Q17-103216	#10-32	1/2
A 9Q17-103220	#10-32	5/8
A 9Q17-103224	#10-32	3/4
A 9Q17-252006	1/4-20	3/16
A 9Q17-252008	1/4-20	1/4
A 9Q17-252010	1/4-20	5/16
A 9Q17-252012	1/4-20	3/8
A 9Q17-252016	1/4-20	1/2
A 9Q17-252020	1/4-20	5/8
A 9Q17-252024	1/4-20	3/4
A 9Q17-311810	5/16-18	5/16
A 9Q17-311812	5/16-18	3/8
A 9Q17-311816	5/16-18	1/2
A 9Q17-311824	5/16-18	3/4
A 9Q17-311828	5/16-18	7/8

NYLON TIPPED SET SCREWS



SELF-LOCKING
NONMARRING


PHONE: 516.328.3300 • FAX: 516.326.8827 • WWW.SDP-SI.COM



> MATERIAL:

Screw - 18-8 Stainless Steel
Tip - Nylon

For engineering assistance for all SDP components, call on our application engineers.

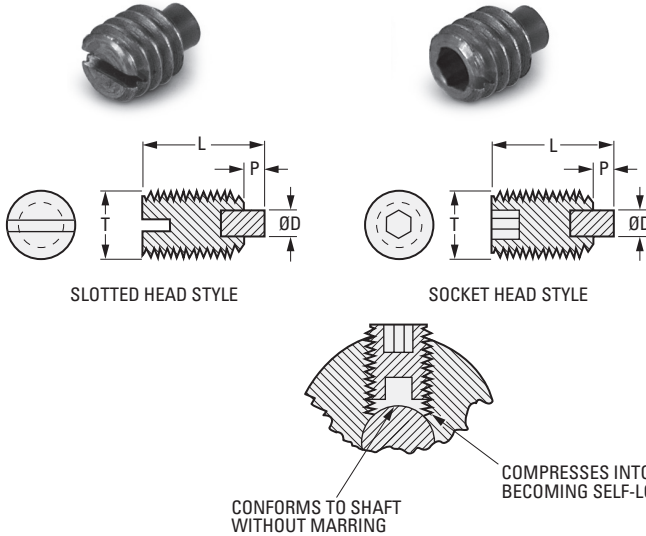

INCH COMPONENT

Catalog Number	T Thread Size	L	P	D Dia.
Slotted Head Style				
A 9X93-SL025610	#2-56	5/32	1/32	1/32
A 9X93-SL044010	#4-40	5/32	1/32	1/16
A 9X93-SL063210	#6-32	5/32	1/32	1/16
A 9X93-SL083215	#8-32	15/64	3/64	3/32
A 9X93-SL102415	#10-24	15/64	3/64	3/32
A 9X93-SL103215	#10-32	15/64	3/64	3/32
A 9X93-SL252020	1/4-20	5/16	1/16	1/8
Socket Head Style				
A 9X93-SO025610	#2-56	5/32	1/32	1/32
A 9X93-SO044010	#4-40	5/32	1/32	1/16
A 9X93-SO063210	#6-32	5/32	1/32	1/16
A 9X93-SO063218	#6-32	9/32	1/32	1/16
A 9X93-SO083215	#8-32	15/64	3/64	3/32
A 9X93-SO083227	#8-32	27/64	3/64	3/32
A 9X93-SO102415	#10-24	15/64	3/64	3/32
A 9X93-SO102427	#10-24	27/64	3/64	3/32
A 9X93-SO103215	#10-32	15/64	3/64	3/32
A 9X93-SO103227	#10-32	27/64	3/64	3/32
A 9X93-SO252020	1/4-20	5/16	1/16	1/8
A 9X93-SO252028	1/4-20	7/16	1/16	1/8

