

CUP POINT

 
PHONE: 516.328.3300 • FAX: 516.326.8827 • WWW.SDP-SI.COM

> MATERIAL:

Stainless Steel

> SPECIFICATION:

Priced Per 100 Pieces



INCH COMPONENT

| Catalog Number | Thread Size | L Length |
|----------------|-------------|----------|
| A 9X17-008002 | #0-80 | 1/16 |
| A 9X17-008003 | #0-80 | 3/32 |
| A 9X17-008004 | #0-80 | 1/8 |
| A 9X17-008006 | #0-80 | 3/16 |
| A 9X17-008008 | #0-80 | 1/4 |
| A 9X17-025602 | #2-56 | 1/16 |
| A 9X17-025603 | #2-56 | 3/32 |
| A 9X17-025604 | #2-56 | 1/8 |
| A 9X17-025606 | #2-56 | 3/16 |
| A 9X17-025608 | #2-56 | 1/4 |
| A 9X17-044004 | #4-40 | 1/8 |
| A 9X17-044006 | #4-40 | 3/16 |
| A 9X17-044008 | #4-40 | 1/4 |
| A 9X17-063204 | #6-32 | 1/8 |
| A 9X17-063206 | #6-32 | 3/16 |
| A 9X17-063208 | #6-32 | 1/4 |
| A 9X17-063210 | #6-32 | 5/16 |
| A 9X17-063212 | #6-32 | 3/8 |
| A 9X17-064004 | #6-40 | 1/8 |
| A 9X17-064006 | #6-40 | 3/16 |
| A 9X17-064008 | #6-40 | 1/4 |
| A 9X17-064010 | #6-40 | 5/16 |
| A 9X17-083204 | #8-32 | 1/8 |
| A 9X17-083206 | #8-32 | 3/16 |

| Catalog Number | Thread Size | L Length |
|----------------|-------------|----------|
| A 9X17-083208 | #8-32 | 1/4 |
| A 9X17-083210 | #8-32 | 5/16 |
| A 9X17-083212 | #8-32 | 3/8 |
| A 9X17-083216 | #8-32 | 1/2 |
| A 9X17-102404 | #10-24 | 1/8 |
| A 9X17-102406 | #10-24 | 3/16 |
| A 9X17-102408 | #10-24 | 1/4 |
| A 9X17-102414 | #10-24 | 7/16 |
| A 9X17-102416 | #10-24 | 1/2 |
| A 9X17-103204 | #10-32 | 1/8 |
| A 9X17-103206 | #10-32 | 3/16 |
| A 9X17-103208 | #10-32 | 1/4 |
| A 9X17-103210 | #10-32 | 5/16 |
| A 9X17-103212 | #10-32 | 3/8 |
| A 9X17-103216 | #10-32 | 1/2 |
| A 9X17-103220 | #10-32 | 5/8 |
| A 9X17-103224 | #10-32 | 3/4 |
| A 9X17-252006 | 1/4-20 | 3/16 |
| A 9X17-252008 | 1/4-20 | 1/4 |
| A 9X17-252010 | 1/4-20 | 5/16 |
| A 9X17-252012 | 1/4-20 | 3/8 |
| A 9X17-252016 | 1/4-20 | 1/2 |
| A 9X17-252020 | 1/4-20 | 5/8 |
| A 9X17-252024 | 1/4-20 | 3/4 |
| A 9X17-311824 | 5/16-18 | 3/4 |
| A 9X17-311828 | 5/16-18 | 7/8 |

- I
- R
- T
- 1
- 2
- 3
- 4
- 5
- 6
- 7
- 8
- 9
- 10**
- 11
- 12
- 13
- 14
- 15
- 16

CUP POINT

 
PHONE: 516.328.3300 • FAX: 516.326.8827 • WWW.SDP-SI.COM

> MATERIAL:

Steel, Black Oxide

> SPECIFICATION:

Priced Per 100 Pieces



- I
- R
- T
- 1
- 2
- 3
- 4
- 5
- 6
- 7
- 8
- 9
- 10**
- 11
- 12
- 13
- 14
- 15
- 16

INCH COMPONENT

| Catalog Number | Thread Size | L Length |
|----------------|-------------|----------|
| A 9Q17-008002 | #0-80 | 1/16 |
| A 9Q17-008003 | #0-80 | 3/32 |
| A 9Q17-008004 | #0-80 | 1/8 |
| A 9Q17-008006 | #0-80 | 3/16 |
| A 9Q17-008008 | #0-80 | 1/4 |
| A 9Q17-025602 | #2-56 | 1/16 |
| A 9Q17-025603 | #2-56 | 3/32 |
| A 9Q17-025604 | #2-56 | 1/8 |
| A 9Q17-025606 | #2-56 | 3/16 |
| A 9Q17-025608 | #2-56 | 1/4 |
| A 9Q17-044003 | #4-40 | 3/32 |
| A 9Q17-044004 | #4-40 | 1/8 |
| A 9Q17-044006 | #4-40 | 3/16 |
| A 9Q17-044008 | #4-40 | 1/4 |
| A 9Q17-044010 | #4-40 | 5/16 |
| A 9Q17-063204 | #6-32 | 1/8 |
| A 9Q17-063206 | #6-32 | 3/16 |
| A 9Q17-063208 | #6-32 | 1/4 |
| A 9Q17-063210 | #6-32 | 5/16 |
| A 9Q17-063212 | #6-32 | 3/8 |
| A 9Q17-064004 | #6-40 | 1/8 |
| A 9Q17-064006 | #6-40 | 3/16 |
| A 9Q17-064008 | #6-40 | 1/4 |
| A 9Q17-064010 | #6-40 | 5/16 |
| A 9Q17-083204 | #8-32 | 1/8 |
| A 9Q17-083206 | #8-32 | 3/16 |
| A 9Q17-083208 | #8-32 | 1/4 |
| A 9Q17-083210 | #8-32 | 5/16 |
| A 9Q17-083212 | #8-32 | 3/8 |

| Catalog Number | Thread Size | L Length |
|----------------|-------------|----------|
| A 9Q17-083216 | #8-32 | 1/2 |
| A 9Q17-102404 | #10-24 | 1/8 |
| A 9Q17-102406 | #10-24 | 3/16 |
| A 9Q17-102408 | #10-24 | 1/4 |
| A 9Q17-102410 | #10-24 | 5/16 |
| A 9Q17-102412 | #10-24 | 3/8 |
| A 9Q17-102414 | #10-24 | 7/16 |
| A 9Q17-102416 | #10-24 | 1/2 |
| A 9Q17-103204 | #10-32 | 1/8 |
| A 9Q17-103206 | #10-32 | 3/16 |
| A 9Q17-103208 | #10-32 | 1/4 |
| A 9Q17-103210 | #10-32 | 5/16 |
| A 9Q17-103212 | #10-32 | 3/8 |
| A 9Q17-103216 | #10-32 | 1/2 |
| A 9Q17-103220 | #10-32 | 5/8 |
| A 9Q17-103224 | #10-32 | 3/4 |
| A 9Q17-252006 | 1/4-20 | 3/16 |
| A 9Q17-252008 | 1/4-20 | 1/4 |
| A 9Q17-252010 | 1/4-20 | 5/16 |
| A 9Q17-252012 | 1/4-20 | 3/8 |
| A 9Q17-252016 | 1/4-20 | 1/2 |
| A 9Q17-252020 | 1/4-20 | 5/8 |
| A 9Q17-252024 | 1/4-20 | 3/4 |
| A 9Q17-311810 | 5/16-18 | 5/16 |
| A 9Q17-311812 | 5/16-18 | 3/8 |
| A 9Q17-311816 | 5/16-18 | 1/2 |
| A 9Q17-311824 | 5/16-18 | 3/4 |
| A 9Q17-311828 | 5/16-18 | 7/8 |

HALF-DOG POINT SOCKET HEAD SET SCREWS





MATERIAL:

Alloy Steel, Case-Hardened to Rc 46-53

PHONE: 516.328.3300 • FAX: 516.326.8827 • WWW.SDP-SI.COM

SPECIFICATION:

Priced Per 100 Pieces

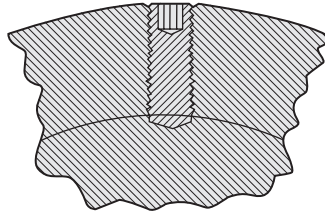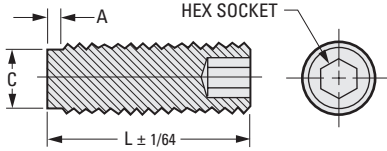

INCH COMPONENT

| Catalog Number | Thread Size | C Dia. | | A Nominal | L Length |
|-----------------|-------------|--------|------|-----------|----------|
| | | Min. | Max. | | |
| S705ZY-D0832H03 | #8-32 | .103 | .109 | .040 | 3/16 |
| S705ZY-D0832H04 | #8-32 | .103 | .109 | .040 | 1/4 |
| S705ZY-D0832H05 | #8-32 | .103 | .109 | .040 | 5/16 |
| S705ZY-D0832H06 | #8-32 | .103 | .109 | .040 | 3/8 |
| S705ZY-D0832H08 | #8-32 | .103 | .109 | .040 | 1/2 |
| S705ZY-D1024H03 | #10-24 | .120 | .127 | .045 | 3/16 |
| S705ZY-D1024H04 | #10-24 | .120 | .127 | .045 | 1/4 |
| S705ZY-D1024H05 | #10-24 | .120 | .127 | .045 | 5/16 |
| S705ZY-D1024H06 | #10-24 | .120 | .127 | .045 | 3/8 |
| S705ZY-D1024H08 | #10-24 | .120 | .127 | .045 | 1/2 |
| S705ZY-D2520H04 | 1/4-20 | .149 | .156 | .063 | 1/4 |
| S705ZY-D2520H05 | 1/4-20 | .149 | .156 | .063 | 5/16 |
| S705ZY-D2520H06 | 1/4-20 | .149 | .156 | .063 | 3/8 |
| S705ZY-D2520H08 | 1/4-20 | .149 | .156 | .063 | 1/2 |
| S705ZY-D2520H10 | 1/4-20 | .149 | .156 | .063 | 5/8 |
| S705ZY-D2520H12 | 1/4-20 | .149 | .156 | .063 | 3/4 |
| S705ZY-D2520H16 | 1/4-20 | .149 | .156 | .063 | 1 |

NYLON TIPPED SET SCREWS



SELF-LOCKING
NONMARRING


PHONE: 516.328.3300 • FAX: 516.326.8827 • WWW.SDP-SI.COM



> MATERIAL:

Screw - 18-8 Stainless Steel
Tip - Nylon

For engineering assistance for all SDP components, call on our application engineers.

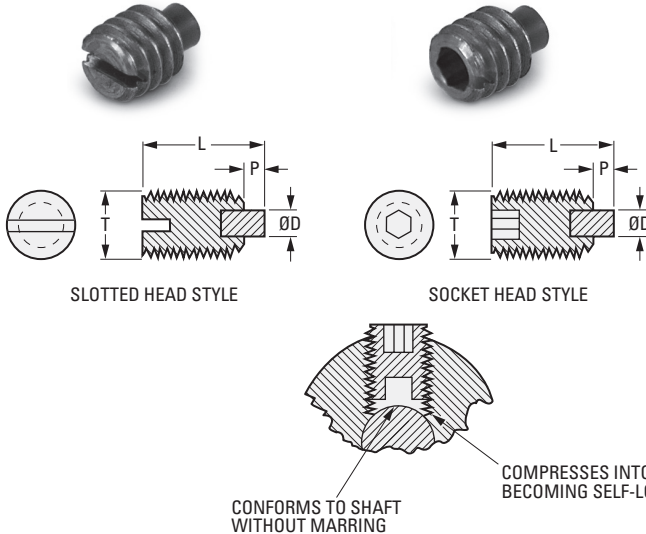

INCH COMPONENT

| Catalog Number | T Thread Size | L | P | D Dia. |
|---------------------------|---------------|-------|------|--------|
| Slotted Head Style | | | | |
| A 9X93-SL025610 | #2-56 | 5/32 | 1/32 | 1/32 |
| A 9X93-SL044010 | #4-40 | 5/32 | 1/32 | 1/16 |
| A 9X93-SL063210 | #6-32 | 5/32 | 1/32 | 1/16 |
| A 9X93-SL083215 | #8-32 | 15/64 | 3/64 | 3/32 |
| A 9X93-SL102415 | #10-24 | 15/64 | 3/64 | 3/32 |
| A 9X93-SL103215 | #10-32 | 15/64 | 3/64 | 3/32 |
| A 9X93-SL252020 | 1/4-20 | 5/16 | 1/16 | 1/8 |
| Socket Head Style | | | | |
| A 9X93-SO025610 | #2-56 | 5/32 | 1/32 | 1/32 |
| A 9X93-SO044010 | #4-40 | 5/32 | 1/32 | 1/16 |
| A 9X93-SO063210 | #6-32 | 5/32 | 1/32 | 1/16 |
| A 9X93-SO063218 | #6-32 | 9/32 | 1/32 | 1/16 |
| A 9X93-SO083215 | #8-32 | 15/64 | 3/64 | 3/32 |
| A 9X93-SO083227 | #8-32 | 27/64 | 3/64 | 3/32 |
| A 9X93-SO102415 | #10-24 | 15/64 | 3/64 | 3/32 |
| A 9X93-SO102427 | #10-24 | 27/64 | 3/64 | 3/32 |
| A 9X93-SO103215 | #10-32 | 15/64 | 3/64 | 3/32 |
| A 9X93-SO103227 | #10-32 | 27/64 | 3/64 | 3/32 |
| A 9X93-SO252020 | 1/4-20 | 5/16 | 1/16 | 1/8 |
| A 9X93-SO252028 | 1/4-20 | 7/16 | 1/16 | 1/8 |



FLAT POINT

 

PHONE: 516.328.3300 • FAX: 516.326.8827 • WWW.SDP-SI.COM

► **MATERIAL:**

Nylon

► **SPECIFICATION:**

Priced Per 100 Pieces

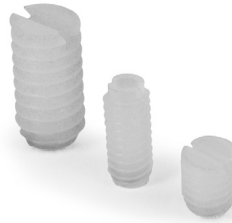

INCH COMPONENT

| Catalog Number | Thread Size | L |
|----------------|-------------|--------|
| A 9M58-25603 | #2-56 | .1875 |
| A 9M58-25604 | #2-56 | .2500 |
| A 9M58-25606 | #2-56 | .3750 |
| A 9M58-25608 | #2-56 | .5000 |
| A 9M58-44002A | #4-40 | .1250 |
| A 9M58-44003A | #4-40 | .1875 |
| A 9M58-44004 | #4-40 | .2500 |
| A 9M58-44005 | #4-40 | .3125 |
| A 9M58-44006 | #4-40 | .3750 |
| A 9M58-44008 | #4-40 | .5000 |
| A 9M58-44010 | #4-40 | .6250 |
| A 9M58-44012 | #4-40 | .7500 |
| A 9M58-44016 | #4-40 | 1.0000 |
| A 9M58-63204 | #6-32 | .2500 |
| A 9M58-63205 | #6-32 | .3125 |
| A 9M58-63206 | #6-32 | .3750 |
| A 9M58-63208 | #6-32 | .5000 |
| A 9M58-63210 | #6-32 | .6250 |
| A 9M58-63212 | #6-32 | .7500 |
| A 9M58-63216 | #6-32 | 1.0000 |
| A 9M58-83204 | #8-32 | .2500 |

| Catalog Number | Thread Size | L |
|----------------|-------------|--------|
| A 9M58-83205 | #8-32 | .3125 |
| A 9M58-83206 | #8-32 | .3750 |
| A 9M58-83208 | #8-32 | .5000 |
| A 9M58-83210 | #8-32 | .6250 |
| A 9M58-83212 | #8-32 | .7500 |
| A 9M58-83216 | #8-32 | 1.0000 |
| A 9M58-03204 | #10-32 | .2500 |
| A 9M58-03205 | #10-32 | .3125 |
| A 9M58-03206 | #10-32 | .3750 |
| A 9M58-03208 | #10-32 | .5000 |
| A 9M58-03210 | #10-32 | .6250 |
| A 9M58-03212 | #10-32 | .7500 |
| A 9M58-03216 | #10-32 | 1.0000 |
| A 9M58-12004 | 1/4-20 | .2500 |
| A 9M58-12006 | 1/4-20 | .3750 |
| A 9M58-12008 | 1/4-20 | .5000 |
| A 9M58-12010 | 1/4-20 | .6250 |
| A 9M58-12012 | 1/4-20 | .7500 |
| A 9M58-12016 | 1/4-20 | 1.0000 |
| A 9M58-12016A | 1/4-20 | 1.0000 |

NEW