
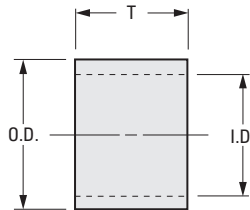


**> MATERIAL:**

300 Series Stainless Steel

PHONE: 516.328.3300 • FAX: 516.326.8827 • WWW.SDP-SI.COM

Other spacers available on special order.

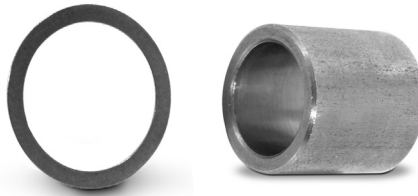

## INCH COMPONENT

Catalog Number	I.D.	O.D.	T Thickness
A 7X 8-C04004	1/8	3/16	.004
A 7X 8-C04006	1/8	3/16	.006
A 7X 8-C04008	1/8	3/16	.008
A 7X 8-C04010	1/8	3/16	.010
A 7X 8-C04012	1/8	3/16	.012
A 7X 8-C04014	1/8	3/16	.014
A 7X 8-C04016	1/8	3/16	.016
A 7X 8-C04031	1/8	3/16	.031
A 7X 8-C04063	1/8	3/16	.063
A 7X 8-C04094	1/8	3/16	.094
A 7X 8-C04125	1/8	3/16	.125
A 7X 8-C04188	1/8	3/16	.188
A 7X 8-C04250	1/8	3/16	.250
A 7X 8-C04375	1/8	3/16	.375
A 7X 8-C04500	1/8	3/16	.500
A 7X 8-C06004	3/16	1/4	.004
A 7X 8-C06006	3/16	1/4	.006
A 7X 8-C06008	3/16	1/4	.008
A 7X 8-C06010	3/16	1/4	.010
A 7X 8-C06012	3/16	1/4	.012
A 7X 8-C06014	3/16	1/4	.014
A 7X 8-C06016	3/16	1/4	.016
A 7X 8-C06031	3/16	1/4	.031
A 7X 8-C06063	3/16	1/4	.063
A 7X 8-C06094	3/16	1/4	.094
A 7X 8-C06125	3/16	1/4	.125
A 7X 8-C06188	3/16	1/4	.188

Catalog Number	I.D.	O.D.	T Thickness
A 7X 8-C06250	3/16	1/4	.250
A 7X 8-C06375	3/16	1/4	.375
A 7X 8-C06500	3/16	1/4	.500
A 7X 8-C08004	1/4	3/8	.004
A 7X 8-C08006	1/4	3/8	.006
A 7X 8-C08008	1/4	3/8	.008
A 7X 8-C08010	1/4	3/8	.010
A 7X 8-C08012	1/4	3/8	.012
A 7X 8-C08014	1/4	3/8	.014
A 7X 8-C08016	1/4	3/8	.016
A 7X 8-C08031	1/4	3/8	.031
A 7X 8-C08063	1/4	3/8	.063
A 7X 8-C08094	1/4	3/8	.094
A 7X 8-C08125	1/4	3/8	.125
A 7X 8-C08188	1/4	3/8	.188
A 7X 8-C08250	1/4	3/8	.250
A 7X 8-C08375	1/4	3/8	.375
A 7X 8-C08500	1/4	3/8	.500
A 7X 8-C10004	5/16	7/16	.004
A 7X 8-C10006	5/16	7/16	.006
A 7X 8-C10008	5/16	7/16	.008
A 7X 8-C10010	5/16	7/16	.010
A 7X 8-C10012	5/16	7/16	.012
A 7X 8-C10014	5/16	7/16	.014
A 7X 8-C10016	5/16	7/16	.016
A 7X 8-C10031	5/16	7/16	.031
A 7X 8-C10063	5/16	7/16	.063

Continued on the next page



- I
- R
- T
- 1
- 2
- 3
- 4
- 5
- 6
- 7
- 8
- 9
- 10
- 11
- 12
- 13
- 14
- 15
- 16

**MATERIAL:**

300 Series Stainless Steel

PHONE: 516.328.3300 • FAX: 516.326.8827 • WWW.SDP-SI.COM

Other spacers available on special order.

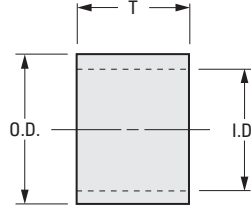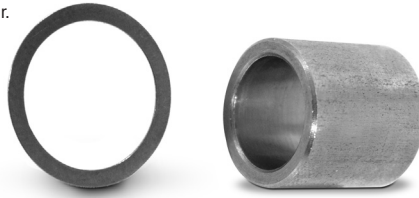

**INCH COMPONENT**

Catalog Number	I.D.	O.D.	T Thickness
A 7X 8-C10094	5/16	7/16	.094
A 7X 8-C10125	5/16	7/16	.125
A 7X 8-C10188	5/16	7/16	.188
A 7X 8-C10250	5/16	7/16	.250
A 7X 8-C10375	5/16	7/16	.375
A 7X 8-C10500	5/16	7/16	.500
A 7X 8-C12004	3/8	1/2	.004
A 7X 8-C12006	3/8	1/2	.006
A 7X 8-C12008	3/8	1/2	.008
A 7X 8-C12010	3/8	1/2	.010
A 7X 8-C12012	3/8	1/2	.012
A 7X 8-C12014	3/8	1/2	.014
A 7X 8-C12016	3/8	1/2	.016
A 7X 8-C12031	3/8	1/2	.031
A 7X 8-C12063	3/8	1/2	.063
A 7X 8-C12094	3/8	1/2	.094
A 7X 8-C12125	3/8	1/2	.125
A 7X 8-C12188	3/8	1/2	.188
A 7X 8-C12250	3/8	1/2	.250
A 7X 8-C12375	3/8	1/2	.375
A 7X 8-C12500	3/8	1/2	.500
A 7X 8-C14004	7/16	9/16	.004
A 7X 8-C14006	7/16	9/16	.006
A 7X 8-C14008	7/16	9/16	.008
A 7X 8-C14010	7/16	9/16	.010
A 7X 8-C14012	7/16	9/16	.012
A 7X 8-C14014	7/16	9/16	.014

Catalog Number	I.D.	O.D.	T Thickness
A 7X 8-C14016	7/16	9/16	.016
A 7X 8-C14031	7/16	9/16	.031
A 7X 8-C14063	7/16	9/16	.063
A 7X 8-C14094	7/16	9/16	.094
A 7X 8-C14125	7/16	9/16	.125
A 7X 8-C14188	7/16	9/16	.188
A 7X 8-C14250	7/16	9/16	.250
A 7X 8-C14375	7/16	9/16	.375
A 7X 8-C14500	7/16	9/16	.500
A 7X 8-C16004	1/2	5/8	.004
A 7X 8-C16006	1/2	5/8	.006
A 7X 8-C16008	1/2	5/8	.008
A 7X 8-C16010	1/2	5/8	.010
A 7X 8-C16012	1/2	5/8	.012
A 7X 8-C16014	1/2	5/8	.014
A 7X 8-C16016	1/2	5/8	.016
A 7X 8-C16031	1/2	5/8	.031
A 7X 8-C16063	1/2	5/8	.063
A 7X 8-C16094	1/2	5/8	.094
A 7X 8-C16125	1/2	5/8	.125
A 7X 8-C16188	1/2	5/8	.188
A 7X 8-C16250	1/2	5/8	.250
A 7X 8-C16375	1/2	5/8	.375
A 7X 8-C16500	1/2	5/8	.500
A 7X 8-C20050	5/8	3/4	.050
A 7X 8-C24050	3/4	7/8	.050

Continued from the previous page

## OUTER RACE SHIM SPACER


 
PHONE: 516.328.3300 • FAX: 516.326.8827 • WWW.SDP-SI.COM

### > MATERIAL:

300 Series Stainless Steel

### > SPECIFICATION:

Priced Per 100 Pieces

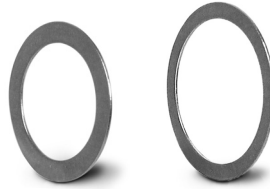

### INCH COMPONENT

Catalog Number	Shaft Size Ref.	I.D. +.005 -.000	O.D. +.000 -.005	T Thickness ± .001
A 7X 8-A04003	1/8	.253	.373	.003
A 7X 8-A04005	1/8	.253	.373	.005
A 7X 8-A04007	1/8	.253	.373	.007
A 7X 8-A04010	1/8	.253	.373	.010
A 7X 8-A04020	1/8	.253	.373	.020
A 7X 8-A06003	3/16	.378	.498	.003
A 7X 8-A06005	3/16	.378	.498	.005
A 7X 8-A06007	3/16	.378	.498	.007
A 7X 8-A06010	3/16	.378	.498	.010
A 7X 8-A06020	3/16	.378	.498	.020
A 7X 8-A08003	1/4	.503	.623	.003
A 7X 8-A08005	1/4	.503	.623	.005
A 7X 8-A08007	1/4	.503	.623	.007
A 7X 8-A08010	1/4	.503	.623	.010
A 7X 8-A08020	1/4	.503	.623	.020
A 7X 8-A12003	3/8	.628	.748	.003
A 7X 8-A12005	3/8	.628	.748	.005
A 7X 8-A12007	3/8	.628	.748	.007
A 7X 8-A12010	3/8	.628	.748	.010
A 7X 8-A12020	3/8	.628	.748	.020


## LAMINATED BRASS SHIM SPACERS

### > MATERIAL:

Laminated Brass

### > SPECIFICATION:

Priced Per 100 Pieces

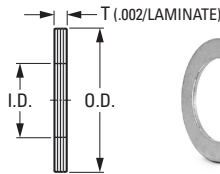

Other spacers available on special order.

### INCH COMPONENT

Catalog Number	I.D.	O.D.	T Thickness
A 7B 8-B04234	.135	.234	.032
A 7B 8-B06375	.193	.375	.032
A 7B 8-B08500	.255	.500	.032
A 7B 8-B09375	.281	.375	.032
A 7B 8-B10370	.312	.370	.032
A 7B 8-B10500	.312	.500	.032
A 7B 8-B11500	.343	.500	.032
A 7B 8-B12498	.375	.498	.032
A 7B 8-B12625	.380	.625	.032
A 7B 8-B14625	.442	.625	.032
A 7B 8-B16750	.505	.750	.032
A 7B 8-B22873	.687	.873	.032

I  
R  
T  
1  
2  
3  
4  
5  
6  
7  
8  
9  
10  
11  
12  
13  
14  
15  
16


## MATERIAL:

Strip Steel

PHONE: 516.328.3300 • FAX: 516.326.8827 • WWW.SDP-SI.COM

## SPECIFICATION:

Priced Per 100 Pieces

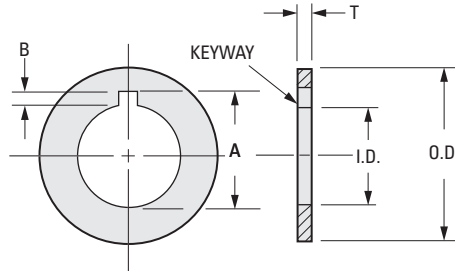

## INCH COMPONENT

Catalog Number	I.D. +.005 -.000	O.D. +.005 -.000	Keyway	A +.010 -.000	B +.007 -.000	T Thickness
A 7C 8-D12002	.376	.625	1/8 x 3/64	.433	.130	.002
A 7C 8-D12004	.376	.625	1/8 x 3/64	.433	.130	.004
A 7C 8-D12006	.376	.625	1/8 x 3/64	.433	.130	.006
A 7C 8-D12010	.376	.625	1/8 x 3/64	.433	.130	.010
A 7C 8-D12020	.376	.625	1/8 x 3/64	.433	.130	.020
A 7C 8-D12025	.376	.625	1/8 x 3/64	.433	.130	.025
A 7C 8-D12032	.376	.625	1/8 x 3/64	.433	.130	.032
A 7C 8-D12062	.376	.625	1/8 x 3/64	.433	.130	.062
A 7C 8-D12125	.376	.625	1/8 x 3/64	.433	.130	.125
A 7C 8-D16001	.501	.750	1/8 x 3/64	.558	.130	.001
A 7C 8-D16002	.501	.750	1/8 x 3/64	.558	.130	.002
A 7C 8-D16005	.501	.750	1/8 x 3/64	.558	.130	.005
A 7C 8-D16010	.501	.750	1/8 x 3/64	.558	.130	.010
A 7C 8-D16015	.501	.750	1/8 x 3/64	.558	.130	.015
A 7C 8-D16125	.501	.750	1/8 x 3/64	.558	.130	.125
A 7C 8-D20006	.626	1.000	5/32 x 1/16	.699	.161	.006
A 7C 8-D20062	.626	1.000	5/32 x 1/16	.699	.161	.062
A 7C 8-D24001	.751	1.125	3/16 x 5/64	.839	.192	.001
A 7C 8-D24015	.751	1.125	3/16 x 5/64	.839	.192	.015
A 7C 8-D24062	.751	1.125	3/16 x 5/64	.839	.192	.062
A 7C 8-D28032	.876	1.375	3/16 x 5/64	.964	.192	.032
A 7C 8-D32001	1.001	1.500	1/4 x 3/32	1.105	.255	.001
A 7C 8-D32002	1.001	1.500	1/4 x 3/32	1.105	.255	.002
A 7C 8-D32005	1.001	1.500	1/4 x 3/32	1.105	.255	.005
A 7C 8-D32008	1.001	1.500	1/4 x 3/32	1.105	.255	.008
A 7C 8-D32010	1.001	1.500	1/4 x 3/32	1.105	.255	.010
A 7C 8-D32015	1.001	1.500	1/4 x 3/32	1.105	.255	.015
A 7C 8-D32093	1.001	1.500	1/4 x 3/32	1.105	.255	.093
A 7C 8-D32125	1.001	1.500	1/4 x 3/32	1.105	.255	.125