


**SHAFT COLLARS**

PHONE: 516.328.3300 • FAX: 516.326.8827 • WWW.SDP-SI.COM

EASY AND PRECISE STROKE ADJUSTMENT  
UP TO .44 in. FINE STROKE ADJUSTMENT

> **MATERIAL:**

Carbon Steel, Black Oxide

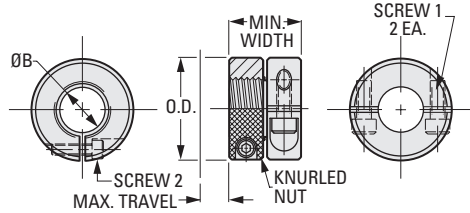

**INCH COMPONENT**

Catalog Number	O.D.	B Bore +.001 -.000	Min. Width	Max.* Travel	Screw 1	Screw 2	Max. Axial Load Capacity lbf	
							Stainless Steel	Steel
S21SAC-025063S	5/8	.250	15/32	.19	#4-40	#2-56	390	790
S21SAC-038088S	7/8	.375		.16	#6-32	#2-56	460	660
S21SAC-050113S	1-1/8	.500	3/4	.32	#8-32	#5-40	690	1310
S21SAC-063131S	1-5/16	.625				#6-32	570	1210
S21SAC-075150S	1-1/2	.750	7/8	.38	#10-32	#6-32	1200	3600
S21SAC-100175S	1-3/4	1.000				#8-32	730	3450
S21SAC-125206S	2-1/16	1.250	1	.44	1/4-20	#8-32	2450	3260
S21SAC-138225S	2-1/4	1.375				2640	3220	
S21SAC-150238S	2-3/8	1.500				2840	3180	

\* Max. Width = Min. Width + Max. Travel

**RUBBER BUMPERS**


SHOCK ABSORBER FOR COMPRESSION LOADS  
OIL- AND CHEMICAL-RESISTANT

> **MATERIAL:**

Buna-N 60-65A Durometer

> **OPERATING TEMPERATURE:**

-20°F to +250°F

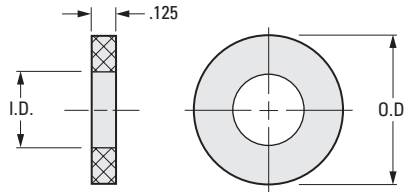

**INCH COMPONENT**

Catalog Number	I.D.	O.D.
S79RUB-025063	.25	.63
S79RUB-038088	.38	.88
S79RUB-050113	.50	1.13
S79RUB-063131	.63	1.31
S79RUB-075150	.75	1.50
S79RUB-100175	1.00	1.75
S79RUB-125206	1.25	2.06
S79RUB-138225	1.38	2.25
S79RUB-150238	1.50	2.38

