

MATERIAL:

Pulley - Polycarbonate, Fiberglass Reinforced
Insert - Aluminum, Knurled, Clear Anodized

FIG. 1


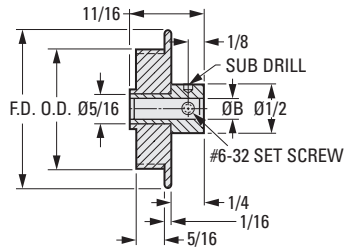


FIG. 2

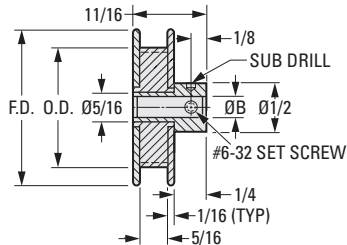

Catalog Number		No. of Grooves	P.D.	O.D.	F.D.	B Bore +.001 -.000
Fig. 1 Single Flange	Fig. 2 Double Flange					
A 6T16-018SF2506	A 6T16-018DF2506	18	.458	.438	.63	.1875
A 6T16-018SF2508	A 6T16-018DF2508	18	.458	.438	.63	.2500
A 6T16-020SF2506	A 6T16-020DF2506	20	.509	.489	.68	.1875
A 6T16-020SF2508	A 6T16-020DF2508	20	.509	.489	.68	.2500
A 6T16-021SF2506	A 6T16-021DF2506	21	.535	.515	.70	.1875
A 6T16-021SF2508	A 6T16-021DF2508	21	.535	.515	.70	.2500
A 6T16-022SF2506	A 6T16-022DF2506	22	.560	.540	.73	.1875
A 6T16-022SF2508	A 6T16-022DF2508	22	.560	.540	.73	.2500
A 6T16-024SF2506	A 6T16-024DF2506	24	.611	.591	.78	.1875
A 6T16-024SF2508	A 6T16-024DF2508	24	.611	.591	.78	.2500
A 6T16-026SF2506	A 6T16-026DF2506	26	.662	.642	.83	.1875
A 6T16-026SF2508	A 6T16-026DF2508	26	.662	.642	.83	.2500
A 6T16-028SF2506	A 6T16-028DF2506	28	.713	.693	.88	.1875
A 6T16-028SF2508	A 6T16-028DF2508	28	.713	.693	.88	.2500
A 6T16-030SF2506	A 6T16-030DF2506	30	.764	.744	.93	.1875
A 6T16-030SF2508	A 6T16-030DF2508	30	.764	.744	.93	.2500
A 6T16-032SF2506	A 6T16-032DF2506	32	.815	.795	.98	.1875
A 6T16-032SF2508	A 6T16-032DF2508	32	.815	.795	.98	.2500
A 6T16-036SF2506	A 6T16-036DF2506	36	.917	.897	1.09	.1875
A 6T16-036SF2508	A 6T16-036DF2508	36	.917	.897	1.09	.2500
A 6T16-040SF2506	A 6T16-040DF2506	40	1.019	.999	1.19	.1875
A 6T16-040SF2508	A 6T16-040DF2508	40	1.019	.999	1.19	.2500