

HARDENED STEEL BALLS

PHONE: 516.328.3300 • FAX: 516.326.8827 • WWW.SDP-SI.COM

Rc 55-62

> MATERIAL:

52100 Chrome Steel or 440 Stainless Steel



> SPECIFICATIONS:

Diameter tolerance:

52100 Chrome Steel is grade #25 ± .000025

440 Stainless Steel is grade #50 ± .00005

Priced Per 10 Pieces

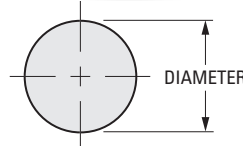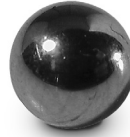

INCH COMPONENT		Diameter
Catalog Number		
Chrome Steel	Stainless Steel	
A 9Q71-02	A 9Y71-02	1/16
A 9Q71-03	A 9Y71-03	3/32
A 9Q71-04	A 9Y71-04	1/8
A 9Q71-05	A 9Y71-05	5/32
A 9Q71-06	A 9Y71-06	3/16
A 9Q71-07	—	7/32
* A 9Q71-08	A 9Y71-08	1/4
A 9Q71-10	A 9Y71-10	5/16
* A 9Q71-12	A 9Y71-12	3/8
A 9Q71-16	A 9Y71-16	1/2

* Available on special order.


NYLON BALLS

LIGHTWEIGHT
WITHSTAND SHOCK
MAXIMUM STRENGTH

> MATERIAL:

Nylon (Polyamide 6/6)

Priced Per 100 pieces

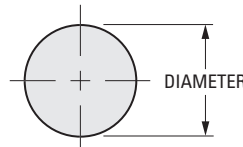

INCH COMPONENT		Diameter ± .003
Catalog Number		
A 9P71-03		3/32
A 9P71-04		1/8
A 9P71-05		5/32
A 9P71-06		3/16
A 9P71-07		7/32
A 9P71-08		1/4
A 9P71-09		9/32
A 9P71-10		5/16
A 9P71-11		11/32
A 9P71-12		3/8

Catalog Number	Diameter ± .003
A 9P71-14	7/16
A 9P71-16	1/2
A 9P71-18	9/16
A 9P71-20	5/8
A 9P71-22	11/16
A 9P71-24	3/4
A 9P71-26	13/16
A 9P71-28	7/8
A 9P71-32	1

I
R
T
1
2
3
4
5
6
7
8
9
10
11
12
13
14
15
16