

# HEXAGONAL NUTS



PHONE: 516.328.3300 • FAX: 516.326.8827 • WWW.SDP-SI.COM

**MATERIAL:**

Alloy Steel or 18-8 Stainless Steel

**FINISH:**

Alloy Steel, Zinc Plated

**SPECIFICATION:**

Priced Per 100 Pieces


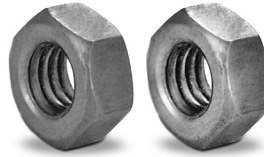


Fig. 1

Fig. 2

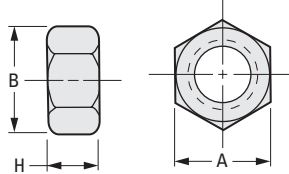

**INCH COMPONENT**

Catalog Number	Thread Size	A +.00 -.01	B +.000 -.015	H +.000 -.015
<b>Fig. 1 Alloy Steel, Zinc Plated</b>				
A 9Q18-080	#0-80	.156	.180	.050
A 9Q18-256	#2-56	.188	.217	.066
A 9Q18-440	#4-40	.250	.289	.098
A 9Q18-632	#6-32	.312	.361	.114
A 9Q18-832	#8-32	.344	.397	.130
A 9Q18-024	#10-24	.375	.433	.130
A 9Q18-032	#10-32	.375	.433	.130
A 9Q18-120	1/4-20	.438	.505	.193
A 9Q18-518	5/16-18	.500	.577	.258
<b>Fig. 2 18-8 Stainless Steel</b>				
A 9X18-080	#0-80	.156	.180	.050
A 9X18-256	#2-56	.188	.217	.066
A 9X18-440	#4-40	.250	.289	.098
A 9X18-632	#6-32	.312	.361	.114
A 9X18-832	#8-32	.344	.397	.130
A 9X18-032	#10-32	.375	.433	.130
A 9X18-120	1/4-20	.438	.505	.193

# HEXAGONAL NYLON INSERT LOCKNUTS

# SDP/SI

VIBRATION-RESISTANT  
NO MARRING OF THREADS  
REUSABLE  
INSERT EFFECTIVE UP TO 250°F

PHONE: 516.328.3300 • FAX: 516.326.8827 • WWW.SDP-SI.COM




**> MATERIAL:**

Locknut - 303 Stainless Steel  
Insert - Nylon

**> SPECIFICATION:**

Priced Per 100 Pieces

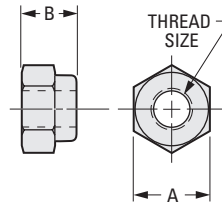

### INCH COMPONENT

Catalog Number	Thread Size	A	B
A 9X23-0256	#2-56	.250	.140
A 9X23-0440	#4-40	.250	.140
A 9X23-0632	#6-32	.313	.172
A 9X23-0832	#8-32	.344	.234
A 9X23-1032	#10-32	.375	.234
A 9X23-2520	1/4-20	.438	.313

- I
- R
- T
- 1
- 2
- 3
- 4
- 5
- 6
- 7
- 8
- 9
- 10
- 11
- 12
- 13
- 14
- 15
- 16

I

# PLASTIC HEXAGONAL NUTS

# SDPSI

LIGHTWEIGHT  
NONCORROSIVE  
VIBRATION-RESISTANT  
NONCONDUCTIVE  
ANTIMAGNETIC

PHONE: 516.328.3300 • FAX: 516.326.8827 • WWW.SDP-SI.COM




R

T

1

► **MATERIAL:**  
Nylon (6/6 Natural)

► **SPECIFICATION:**  
Priced Per 100 Pieces

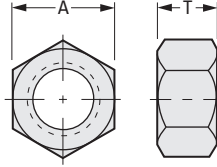

2

3

## INCH COMPONENT

Catalog Number	Thread Size	A	T
A 9M62-0256	#2-56	3/16	1/16
A 9M62-0440	#4-40	1/4	3/32
A 9M62-0632	#6-32	5/16	1/8
A 9M62-0832	#8-32	11/32	1/8
A 9M62-1024	#10-24	3/8	9/64
A 9M62-1032	#10-32	3/8	9/64
A 9M62-2520	1/4-20	7/16	13/64
A 9M62-3118	5/16-18	1/2	17/64
A 9M62-3716	3/8-16	9/16	21/64
A 9M62-5013	1/2-13	3/4	7/16
A 9M62-6211	5/8-11	15/16	35/64

4

5

6

7

8

9

10

11

12

13

14

15

16